


BIF型(轴端未加工品)

DN值

70000

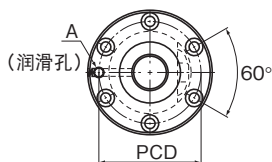

公称型号	滚珠丝杠驱动型							螺母			
	丝杠轴 外径	导程	钢球 中心直径	沟槽谷径	负荷 圈数	基本额定载荷		外径	法兰直径	全长	
						Ca kN	Coa kN				
BIF 1605-5	16	5	16.75	13.2	1×2.5	7.4	13.9	40	60	56	10
BIF 1810-3	18	10	18.8	15.5	1×1.5	5.1	9.6	42	65	75	12
BIF 2005-5	20	5	20.75	17.2	1×2.5	8.3	17.4	44	67	56	11
BIF 2505-5	25	5	25.75	22.2	1×2.5	9.2	22	50	73	55	11

公称型号的构成例

BIF2005-5 RR G0 +610L C5 A

公称型号

轴向间隙标记(※2)

精度标记(※3)


轴端未加工品标记(A或者B)

密封圈标记(※1)

丝杠轴总长度(单位mm)

(※1)参照A15-380。(※2)参照A15-19。(※3)参照A15-12。

轴端未加工品精密滚珠丝杠

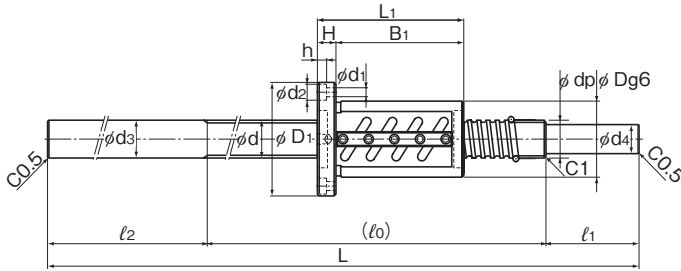

单位：mm

尺寸							丝杠轴尺寸							螺母质量 kg	轴质量 kg/m	容许转速 min ⁻¹
B ₁	PCD	d ₁	d ₂	h	润滑孔 A	轴端未加工 标记	全长 L	l ₀	l ₁	l ₂	d ₃	d ₄				
46	50	4.5	8	4.5	M6	A	410	200	50	160	16	12.8	0.56	0.92	4170	
							510	300								
							610	400								
							710	500								
63	53	5.5	9.5	5.5	M6	A	410	200	50	160	18	15.3	0.75	1.62	3720	
							510	300								
							610	400								
							710	500								
							810	600								
45	55	5.5	9.5	5.5	M6	A	410	200	50	160	20	15.3	0.57	1.65	3370	
							510	300								
							610	400								
							710	500								
							810	600								
						B	610	300	50	260	20	16.8	0.57	1.65	3370	
							710	400								
44	61	5.5	9.5	5.5	M6	A	520	300	60	160	25	20.3	0.75	2.84	2710	
							620	400								
							720	500								
							820	600								
							1020	800								
							1220	1000								
						B	1420	1200	60	260	25	21.8	0.75	2.84	2710	
							720	400								
820	500															

滚珠丝杠