


BNF型(轴端未加工品)

DN值

70000

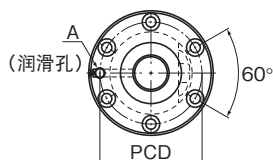

公称型号	滚珠丝杠驱动型							螺母			
	丝杠轴 外 径	导程	钢球 中心直径	沟槽谷径	负荷 圈数	基本额定载荷		外径	法兰直径	全长	
	d	Ph	dp	dc	列×圈	Ca kN	C ₀ a kN	D	D ₁	L ₁	H
BNF 1605-2.5	16	5	16.75	13.2	1×2.5	7.4	13.9	40	60	41	10
BNF 1810-2.5	18	10	18.8	15.5	1×2.5	7.8	15.9	42	65	69	12
BNF 2005-5	20	5	20.75	17.2	2×2.5	15.1	35	44	67	56	11
BNF 2505-5	25	5	25.75	22.2	2×2.5	16.7	44	50	73	55	11

公称型号的构成例

BNF2005-5 RR G1 +610L C5 A

公称型号

轴向往隙标记(※2)

精度标记(※3)


轴端未加工品标记(A或者B)

密封圈标记(※1)

丝杠轴总长度(单位mm)

(※1)参照A15-380。(※2)参照A15-19。(※3)参照A15-12。

轴端未加工品精密滚珠丝杠

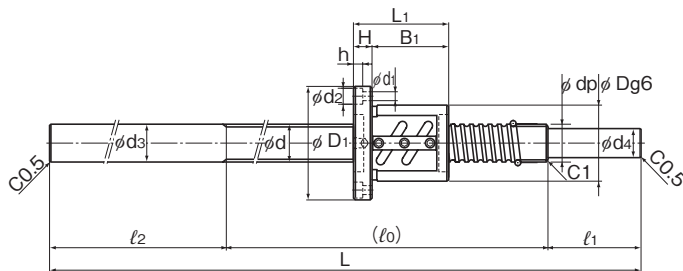

单位: mm

尺寸							丝杠轴尺寸								螺母 质量	轴 质量	容许 转速
	B _i	PCD	d _i	d ₂	h	润滑孔 A	轴端 未加工 标记	全长 L	ℓ ₀	ℓ ₁	ℓ ₂	d ₃	d ₄	kg			
	31	50	4.5	8	4.5	M6	A	410	200	50	160	16	12.8	0.37	0.92	4170	
								510	300								
								610	400								
								710	500						1.25		
	57	53	5.5	9.5	5.5	M6	A	410	200	50	160	18	15.3	0.67	1.62	3720	
								510	300								
								610	400								
								710	500								
								810	600								
	45	55	5.5	9.5	5.5	M6	A	410	200	50	160	20	15.3	0.57	1.65	3370	
								510	300								
								610	400								
								710	500								
								810	600								
								1010	800								
							B	610	300	50	260	20	16.8				
								710	400								
	44	61	5.5	9.5	5.5	M6	A	520	300	60	160	25	20.3	0.75	2.84	2710	
								620	400								
								720	500								
								820	600								
								1020	800								
								1220	1000								
								1420	1200								
							B	720	400	60	260	25	21.8				
								820	500								

滚珠丝杠