


BNF型(轴端未加工品)

DN值

70000

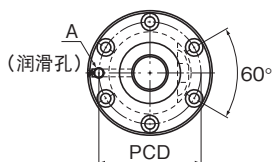

公称型号	滚珠丝杠驱动型							螺母			
	丝杠轴 外径	导程	钢球 中心直径	沟槽谷径	负荷 圈数	基本额定载荷		外径	法兰直径	全长	
						Ca	C _{0a}				
d	Ph	dp	dc	列×圈	kN	kN	D	D ₁	L ₁	H	
BNF 2510A-2.5	25	10	26.3	21.4	1×2.5	15.8	33	58	85	70	18
BNF 2806-5	28	6	28.75	25.2	2×2.5	17.5	49.4	55	85	68	12
BNF 3205-5	32	5	32.75	29.2	2×2.5	18.5	56.4	58	85	56	12

公称型号的构成例

BNF2806-10 RR G1 +1020L C5 A

公称型号

轴向间隙标记(※2)

精度标记(※3)


轴端未加工品标记(A或者B)

密封圈标记(※1)

丝杠轴总长度(单位mm)

(※1)参照▣15-380。(※2)参照▣15-19。(※3)参照▣15-12。

轴端未加工品精密滚珠丝杠

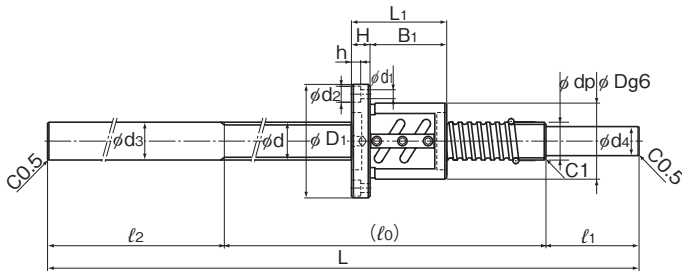

单位：mm

尺寸							丝杠轴尺寸						螺母 质量 kg	轴 质量 kg/m	容许 转速 min ⁻¹	
B _i	PCD	d ₁	d ₂	h	润滑孔 A	轴端 未加工 标记	全长 L	l ₀	l ₁	l ₂	d ₃	d ₄				
52	71	6.6	11	6.5	M6	A	620	400	60	160	25	20.3	1.43	2.68	2660	
							820	600								
							1020	800								
							1220	1000								
							1420	1200								
56	69	6.6	11	6.5	M6	A	520	300	60	160	28	20.3	1.13	3.89	2430	
							620	400								
							720	500								
							920	700								
							1020	800								
						B	1220	1000	70	250	28	24.8	1.13	3.89	2430	
							1420	1200								
							720	400								330
							920	500								
							1100	700								
44	71	6.6	11	6.5	M6	A	730	500	70	160	32	25.3	0.93	5.03	2130	
							930	700								
							1230	1000								
							1430	1200								
							1630	1400								
							1830	1600								27.8

滚珠丝杠