



DIK型(精密滚珠丝杠) 预压型

DN值	70000
-----	-------

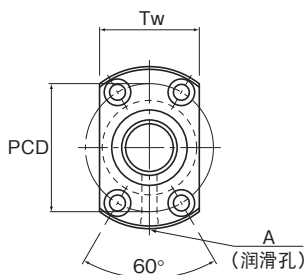

公称型号	丝杠轴 外 径 d	导程 Ph	钢球 中心直径 dp	沟槽谷径 dc	负荷 圈数 列×圈	基本额定载荷		刚性 K N/μm
						Ca kN	Ca kN	
DIK 1404-4	14	4	14.5	11.8	2×1	3	5.1	190
DIK 1404-6	14	4	14.5	11.8	3×1	4.2	7.7	280
DIK 1605-6	16	5	16.75	13.2	3×1	7.4	13	310
DIK 2004-6	20	4	20.5	17.8	3×1	5.2	11.6	380
DIK 2004-8	20	4	20.5	17.8	4×1	6.6	15.5	510
DIK 2005-6	20	5	20.75	17.2	3×1	8.5	17.3	310
DIK 2006-6	20	6	21	16.4	3×1	11.4	21.5	410
DIK 2008-4	20	8	21	16.4	2×1	8.1	14.4	280
DIK 2504-6	25	4	25.5	22.8	3×1	5.7	15	470
DIK 2504-8	25	4	25.5	22.8	4×1	7.4	19.9	620
DIK 2505-6	25	5	25.75	22.2	3×1	9.7	22.6	490
DIK 2506-4	25	6	26	21.4	2×1	9.1	18	330
DIK 2506-6	25	6	26	21.4	3×1	12.8	27	490
DIK 2508-4	25	8	26	21.4	2×1	9.2	18.8	340
DIK 2508-6	25	8	26	21.4	3×1	13.1	28.1	500
DIK 2510-4	25	10	26	21.6	2×1	9	18	330

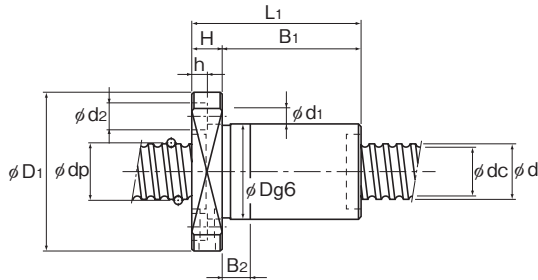

单位：mm

	螺母尺寸										丝杠轴的 惯性力矩/mm ²	螺母 质量 kg	轴 质量 kg/m	容许 转速 min ⁻¹
	外径	法兰直径	全长	H	B ₁	B ₂	PCD	d ₁ × d ₂ × h	Tw	润滑孔				
	D	D ₁	L ₁						A					
	26	45	48	10	38	10	35	4.5 × 8 × 4.5	29	M6	2.96 × 10 ⁻⁸	0.2	1	4820
	26	45	60	10	50	10	35	4.5 × 8 × 4.5	29	M6	2.96 × 10 ⁻⁸	0.23	1	4820
	30	49	60	10	50	10	39	4.5 × 8 × 4.5	31	M6	5.05 × 10 ⁻⁸	0.3	1.25	4170
	32	56	62	11	51	15	44	5.5 × 9.5 × 5.5	35	M6	1.23 × 10 ⁻⁷	0.34	2.18	3410
	32	56	70	11	59	15	44	5.5 × 9.5 × 5.5	35	M6	1.23 × 10 ⁻⁷	0.37	2.18	3410
	34	58	61	11	50	10	46	5.5 × 9.5 × 5.5	36	M6	1.23 × 10 ⁻⁷	0.38	2.06	3370
	35	58	76	11	65	15	46	5.5 × 9.5 × 5.5	36	M6	1.23 × 10 ⁻⁷	0.48	1.93	3330
	35	58	69	11	58	15	46	5.5 × 9.5 × 5.5	36	M6	1.23 × 10 ⁻⁷	0.45	2.06	3330
	38	63	63	11	52	15	51	5.5 × 9.5 × 5.5	39	M6	3.01 × 10 ⁻⁷	0.43	3.5	2740
	38	63	71	11	60	15	51	5.5 × 9.5 × 5.5	39	M6	3.01 × 10 ⁻⁷	0.47	3.5	2740
	40	63	61	11	50	10	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.47	3.35	2710
	40	63	60	11	49	10	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.46	3.19	2690
	40	63	72	11	61	15	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.54	3.19	2690
	40	63	71	12	59	15	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.54	3.35	2690
	40	63	94	12	82	25	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.68	3.35	2690
	40	63	85	15	70	20	51	5.5 × 9.5 × 5.5	41	M6	3.01 × 10 ⁻⁷	0.65	3.45	2690

注) 安装OZ自润滑器时, 螺母全长尺寸会增加。详细内容请参照图A15-390。

关于公称型号的构成, 请参照图A15-262。