



BK型 固定侧角型支承单元

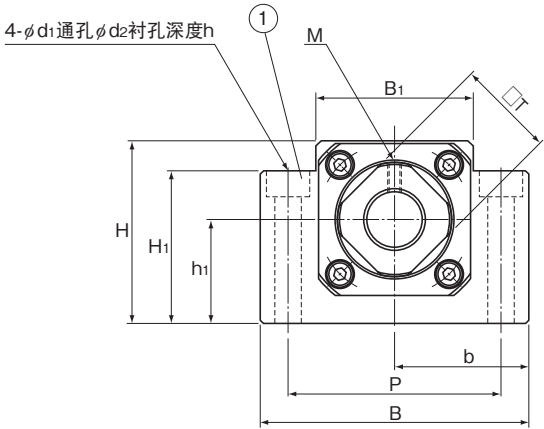

公称型号	轴径										
	d	L	L ₁	L ₂	L ₃	B	H	b ±0.02	h ₁ ±0.02	B ₁	H ₁
BK 10	10	25	5	29	5	60	39	30	22	34	32.5
BK 12	12	25	5	29	5	60	43	30	25	35	32.5
BK 15	15	27	6	32	6	70	48	35	28	40	38
BK 17	17	35	9	44	7	86	64	43	39	50	55
BK 20	20	35	8	43	8	88	60	44	34	52	50
BK 25	25	42	12	54	9	106	80	53	48	64	70
BK 30	30	45	14	61	9	128	89	64	51	76	78
BK 35	35	50	14	67	12	140	96	70	52	88	79
BK 40	40	61	18	76	15	160	110	80	60	100	90

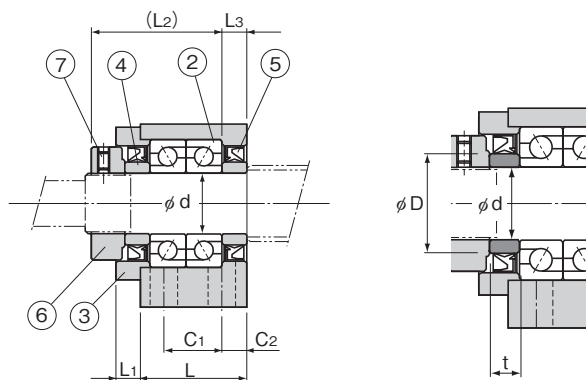

套环详情

单位: mm

	P	C_1	C_2	d_1	d_2	h	M	T	D	t	使用轴承	质量 kg
	46	13	6	6.6	10.8	5	M3	16	13.9	5	相当于7000 (DF P5)	0.39
	46	13	6	6.6	10.8	1.5	M3	19	14.9	5	相当于7001 (DF P5)	0.41
	54	15	6	6.6	11	6.5	M3	22	19.5	6	相当于7002 (DF P5)	0.57
	68	19	8	9	14	8.5	M4	24	23.4	7	相当于7203 (DF P5)	1.27
	70	19	8	9	14	8.5	M4	30	27.4	8	相当于7004 (DF P5)	1.19
	85	22	10	11	17.5	11	M5	35	31.3	9	相当于7205 (DF P5)	2.3
	102	23	11	14	20	13	M6	40	37.3	9	相当于7206 (DF P5)	3.32
	114	26	12	14	20	13	M8	50	44.3	12	相当于7207 (DF P5)	4.33
	130	33	14	18	26	17.5	M8	50	49.4	15	相当于7208 (DF P5)	6.5

滚珠丝杠的外部设备

部件编号	部件名	个数
1	支承座	1
2	轴承	1套
3	固定盖	1
4	套环	2
5	密封圈	2
6	锁紧螺母	1
7	内六角固定螺丝 (配有垫块)	1