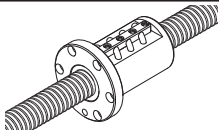
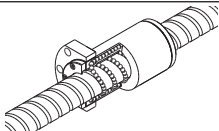
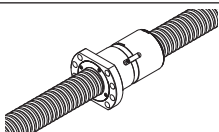
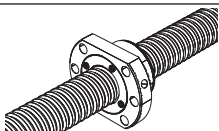
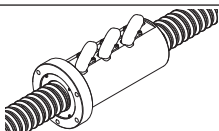
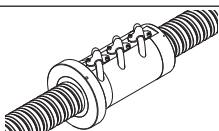
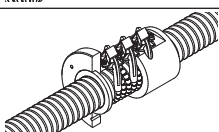
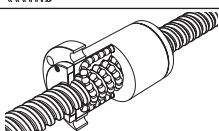


滾珠螺桿

各種型號的特徵

滾珠保持器型精密滾珠螺桿（定位）

類型	型號		特徵	
定位	SBN-V型		高速	
	SBK型		高速、大導程	
	SDAN-V型		雙螺帽、高速、緊湊型	
	SDAN-VX型			
	SDA-V型		高速、緊湊型、標準-超大導程	
	SDA-VZ型			
	HBN-V型		高負荷、高速	
	HBN-K型 HBN-KA型		高負荷、高速	
	HBN型		高負荷、高速	
	SBKH型		高負荷、高速、大導程	

滾珠保持器型精密滾珠螺桿（定位）

	滾珠保持器	小型化	高負荷容量	預壓	DN値	軸徑 (mm)	導程 (mm)	頁數
	●			●	130000	16~32	4~10	▲15-74
				●	160000	25~50	8~20	▲15-76
	●			●	130000	15-32	10-32	▲15-78
				●	160000	36~55	20~36	
				●	210000	36~50	36~50	▲15-80
	●	●		●	160000	31~50	10~40	▲15-82
				●	130000	31~63	10~40	
	●	●		●	160000	14~50	4~50	▲15-88
				●	100000	10~25	4~50	
				●	130000	28~50	5~50	
	●		●		160000	50~80	10~25	▲15-100
	●		●		120000	63~140	16~50	▲15-102
	●		●		130000	32~63	10~20	▲15-108
	●		●		130000	63~120	32~60	▲15-110