



Typ ST / ST-B

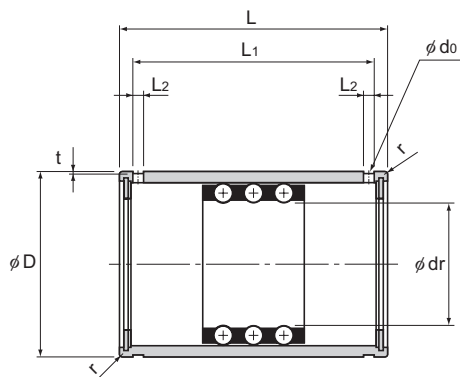

Typ ST
(für geringe Belastungen)

Baureihe/-größe	Maximale Hublänge				
		Innendurchmesser		Außendurchmesser	
		dr	Toleranz	D	Toleranz
ST 40 ST 40B	108 66	40	+0,041 +0,025	60	0 -0,013
ST 45 ST 45B	108 66	45		65	
ST 50 ST 50B	138 88	50		72	
ST 55 ST 55B	138 88	55	+0,049 +0,030	80	0 -0,015
ST 60 ST 60B	138 88	60		85	
ST 70 ST 70B	138 88	70		95	
ST 80 ST 80B	132 76	80		110	
ST 90 ST 90B	132 76	90	+0,058 +0,036	120	0 -0,018
ST 100 ST 100B	132 76	100		130	

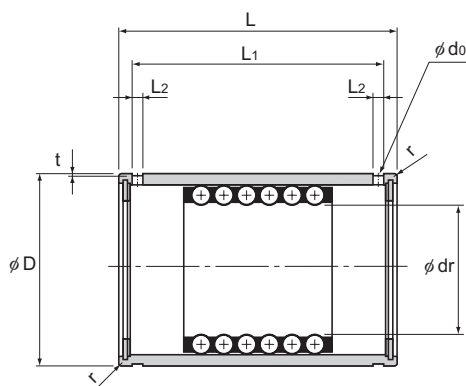

Typ ST-B
(für mittlere Belastungen)

Einheit: mm

								Dynamische Tragzahl	Statische Tragzahl	Gewicht
Länge		Toleranz	L ₁	L ₂	t	d ₀	r	C kN	C ₀ kN	g
L										
80		0 -0,3	73,3	2,5	0,7	2,5	1,5	12,5 25	6,18 12,4	570 635
80			73,3	2,5	0,7	2,5	1,5	12,6 25,2	6,76 13,5	625 695
100			92,4	3	1	3	1,5	16,3 32,5	8,82 17,7	910 1020
100			92,4	3	1	3	2	16,6 33	9,71 19,3	1270 1380
100		0 -0,4	92,4	3	1	3	2	16,8 33,6	10,5 21	1360 1480
100			92,4	3	1	3	2	16,9 33,8	11,7 23,3	1530 1670
100			92	3	1,5	3	2	21,3 42,5	15,3 30,6	2220 2430
100			92	3	1,5	3	2	21,7 43,3	16,9 33,7	2440 2670
100			92	3	1,5	3	2	22 43,9	18,3 36,8	2670 2910