


Model FBL 35K

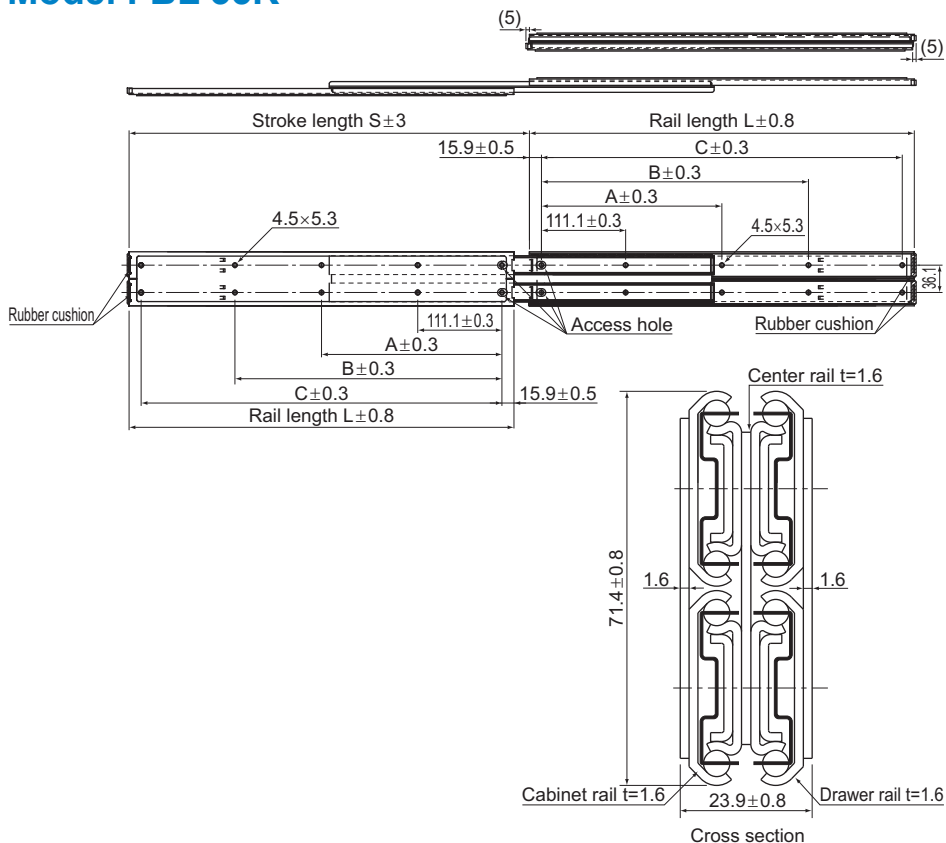

Unit: mm

| Rail length L (±0.8) | Stroke S (±3) | Mounting hole dimensions | | | Mounting hole | | Permissible load N/pair | Mass kg/pair |
|----------------------------|---------------------|--------------------------|-------|-------|----------------|-----------------|----------------------------|-----------------|
| | | A | B | C | Drawer rail | Cabinet rail | | |
| 305 | 327 | — | 149.2 | 273 | 4 | 4 | 2670 | 4.04 |
| 356 | 378 | — | 200 | 323.8 | 4 | 4 | 2630 | 4.8 |
| 406 | 429 | — | 250.8 | 374.6 | 4 | 4 | 2540 | 5.6 |
| 457 | 480 | 212.7 | 301.6 | 425.4 | 5 | 5 | 2450 | 6.04 |
| 508 | 530 | 238.1 | 352.4 | 476.2 | 5 | 5 | 2360 | 6.92 |
| 559 | 581 | 263.5 | 403.2 | 527 | 5 | 5 | 2250 | 7.56 |
| 610 | 632 | 288.9 | 454 | 577.8 | 5 | 5 | 2120 | 8.4 |
| 660 | 683 | 314.3 | 504.8 | 628.6 | 5 | 5 | 1960 | 9 |
| 711 | 734 | 339.7 | 555.6 | 679.4 | 5 | 5 | 1780 | 9.68 |

Notes: The Permissible Load and Mass each indicate when used as a pair of 2 units.


The product has a rubber cushion. If desiring to keep the length within the rail length when storing the product, remove the rubber cushion.

Model number coding

FBL35K +711L

Model number Overall rail length (mm)

Model FBL 56H

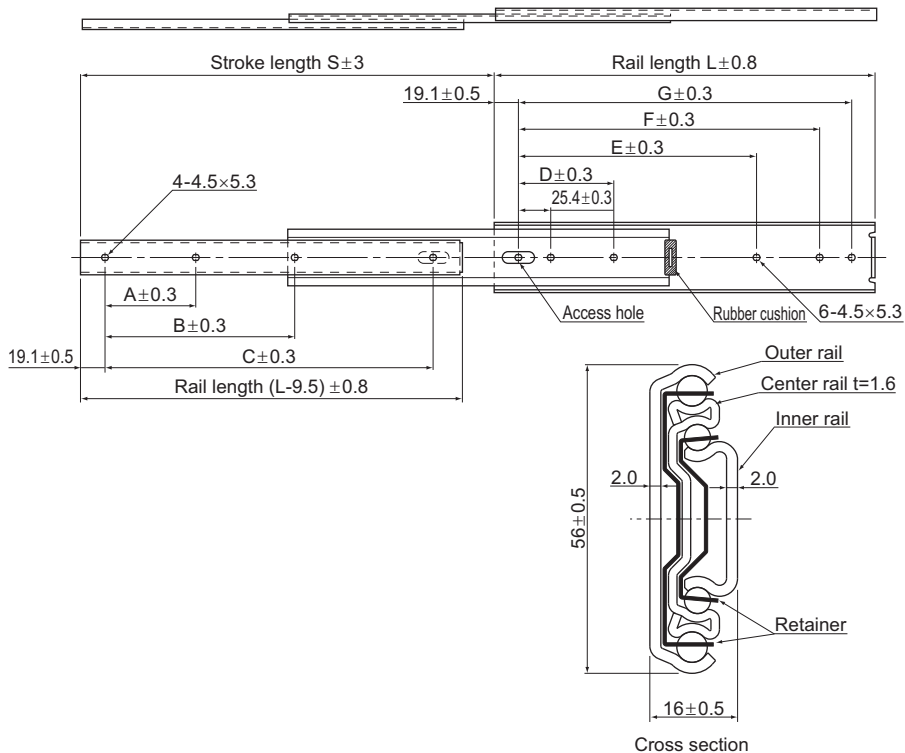

Unit: mm

| Rail length L (±0.8) | Stroke S (±3) | Mounting hole dimensions | | | | | | | Mounting hole | | Permissible load N/pair | Mass kg/pair |
|----------------------------|---------------------|--------------------------|-------|-------|-------|-------|-------|-------|---------------|---------------|----------------------------|-----------------|
| | | A | B | C | D | E | F | G | Inner rail | Outer rail | | |
| 305 | 330 | 76.2 | 177.8 | 254 | 76.2 | 190.5 | 241.3 | 266.7 | 4 | 6 | 961 | 1.76 |
| 356 | 381 | 101.6 | 203.2 | 304.8 | 88.9 | 215.9 | 292.1 | 317.5 | 4 | 6 | 951 | 2.04 |
| 406 | 432 | 127 | 228.6 | 355.6 | 127 | 241.3 | 342.9 | 368.3 | 4 | 6 | 941 | 2.36 |
| 457 | 483 | 127 | 279.4 | 406.4 | 127 | 292.1 | 393.7 | 419.1 | 4 | 6 | 922 | 2.64 |
| 508 | 533 | 152.4 | 304.8 | 457.2 | 152.4 | 317.5 | 444.5 | 469.9 | 4 | 6 | 902 | 2.96 |
| 559 | 584 | 177.8 | 330.2 | 508 | 177.8 | 342.9 | 495.3 | 520.7 | 4 | 6 | 882 | 3.24 |
| 610 | 635 | 177.8 | 381 | 558.8 | 177.8 | 393.7 | 546.1 | 571.5 | 4 | 6 | 863 | 3.6 |
| 660 | 686 | 203.2 | 406.4 | 609.6 | 203.2 | 419.1 | 596.9 | 622.3 | 4 | 6 | 843 | 3.84 |
| 711 | 737 | 228.6 | 431.8 | 660.4 | 228.6 | 444.5 | 647.7 | 673.1 | 4 | 6 | 824 | 4.06 |
| 762 | 787 | 228.6 | 457.2 | 711.2 | 228.6 | 469.9 | 698.5 | 723.9 | 4 | 6 | 784 | 4.44 |

Note: The Permissible Load and Mass each indicate when used as a pair of 2 units.

Model number coding

FBL56H +406L

Model number Overall rail length (mm)