



FK Round Type Support Unit on the Fixed Side

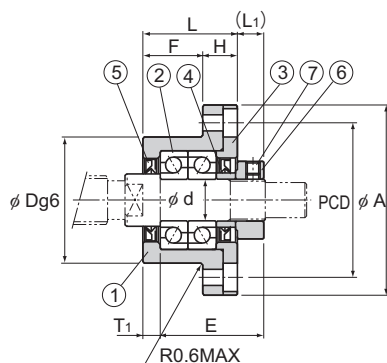


Mounting method A

4- ϕd_1 through hole,
 ϕd_2 counter bore depth h
 (90° equidistant)

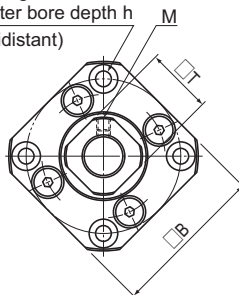

Models FK 10 to 30

Model No.	Shaft diameter	L	H	F	E	D	A	PCD	B
	d								
FK 10	10	27	10	17	29.5	34 -0.009 -0.025	52	42	42
FK 12	12	27	10	17	29.5	36 -0.009 -0.025	54	44	44
FK 15	15	32	15	17	36	40 -0.009 -0.025	63	50	52
FK 20	20	52	22	30	50	57 -0.01 -0.029	85	70	68
FK 25	25	57	27	30	60	63 -0.01 -0.029	98	80	79
FK 30	30	62	30	32	61	75 -0.01 -0.029	117	95	93

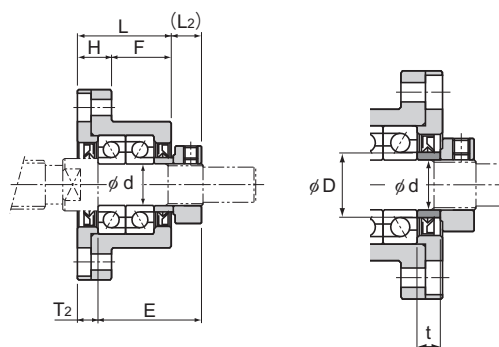

Mounting method B

Collar details

Unit: mm

	Installation procedure A		Installation procedure B		d_1	d_2	h	M	T	D	t	Bearing used	Mass kg
	L_1	T_1	L_2	T_2									
	7.5	5	8.5	6	4.5	8	4	M3	16	13.9	5.5	7000 equivalent (DF P5)	0.21
	7.5	5	8.5	6	4.5	8	4	M3	19	14.9	5.5	7001 equivalent (DF P5)	0.22
	10	6	12	8	5.5	9.5	6	M3	22	19.5	10	7002 equivalent (DF P5)	0.39
	8	10	12	14	6.6	11	10	M4	30	25	11	7204 equivalent (DF P5)	1.09
	13	10	20	17	9	15	13	M5	35	31.3	15	7205 equivalent (DF P5)	1.49
	11	12	17	18	11	17.5	15	M6	40	37.3	9	7206 equivalent (DF P5)	2.32

Part No.	Part name	No. of units
1	Housing	1
2	Bearing	1 set
3	Holding lid	1
4	Collar	2
5	Seal	2
6	Lock Nut	1
7	Hexagonal socket-head setscrew (with a set piece)	1