




Double-Row Cylindrical Roller Type Cam Follower

NUCF-AB

Double-row cylindrical roller type has been added to the lineup
It features a grease nipple pre-attached to a hexagon socket at both ends of a stud

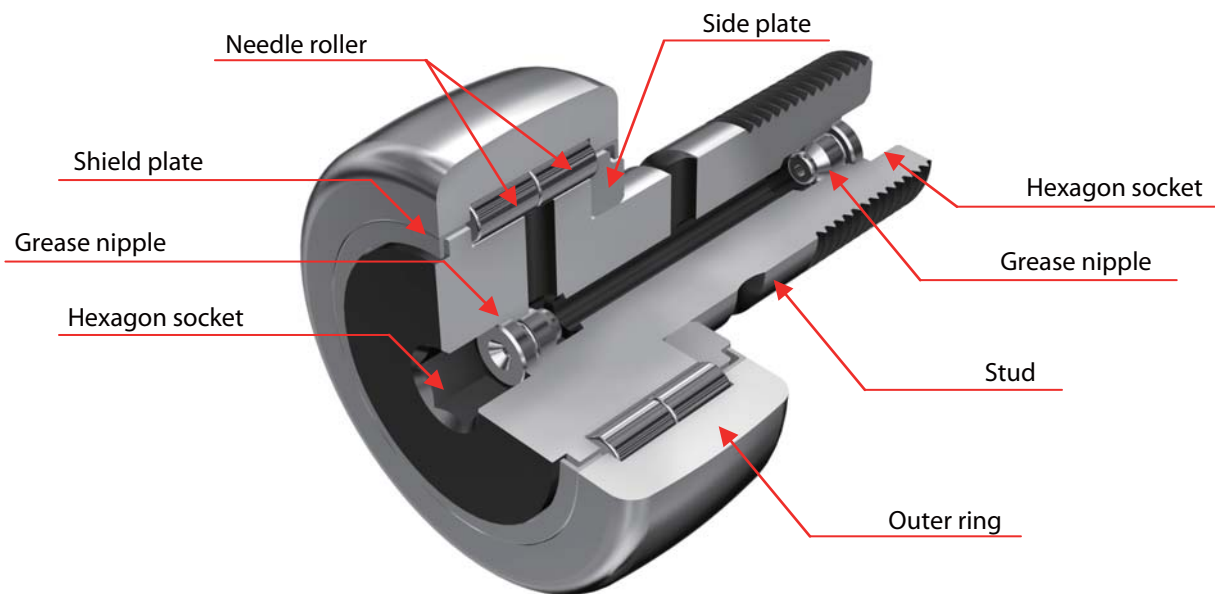

Structure of Double-row Cylindrical Roller Type Cam Follower Model NUCF-AB

● Features

This product employs the double-row cylindrical roller type generally used in Europe.

Two rows of cylindrical rollers built into the model NUCF-AB Cam Follower enable it to receive a high radial load.


Since a grease nipple is pre-attached to a hexagon socket at both ends of the stud, there is no need to mount a nipple or plug; the product can be used out of the box.

Note) Model NUCF-AB corresponds to model numbers 16 to 30-2.


● Easy Attachment and Maintenance

A hex wrench can be used to fix either the head end of the stand or the thread end, and greasing is possible from either end. The unit can be installed and maintained without concern for installation space, thereby boosting operating efficiency.

In Case of Interference at the Stud Head Side

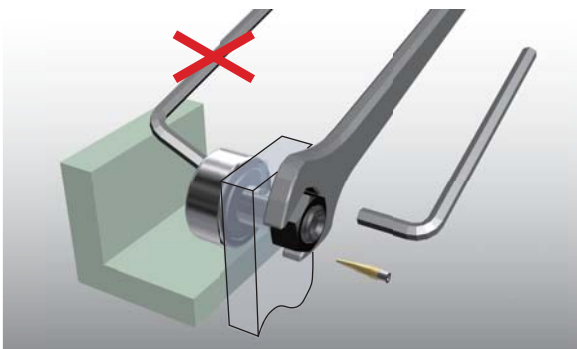


In Case of Interference at the Stud Thread Side

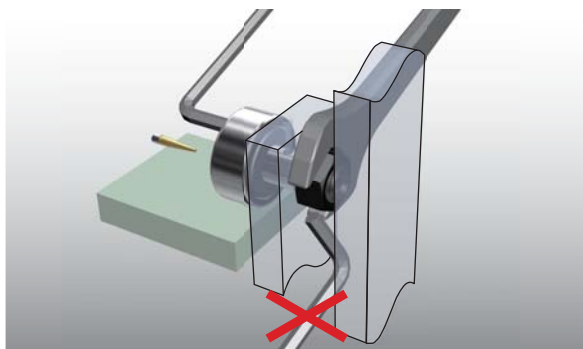

Model Number Coding Example

NUCF16 R - AB

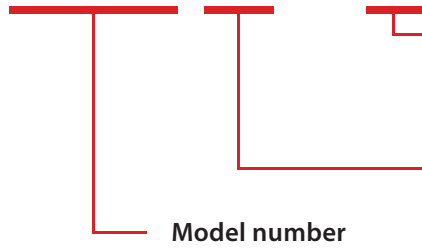


AB : Grease nipple attached at both the stud head and thread ends

No symbol : Cylindrical outer ring

R : Spherical outer ring

Model number

Dimensional Drawing, Dimensional Table

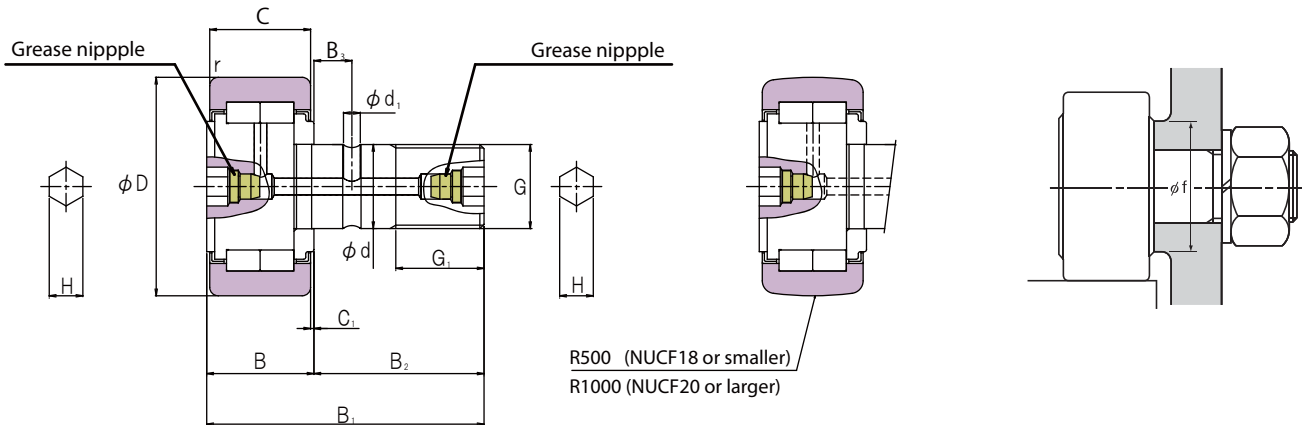

Stud diameter	Model No.	Main dimensions											Basic load rating		Maximum permissible load	Track load capacity		Rotational speed limit					
		Outer diameter	Outer ring width	Threaded	G ₁	B	Overall length	B ₂	B ₃	C ₁	d ₁	H	r _{min}	f (Min.)		C	C ₀		F ₀	Cylindrical outer ring	Spherical outer ring		
d		D	C	G	G ₁	B	B ₁	B ₂	B ₃	C ₁	d ₁	H	r _{min}	f (Min.)	C	C ₀	F ₀	kN	kN	kN	kN	kN	min ⁻¹
16	NUCF16-AB	35	18	M16 × 1.5	17	19.5	52	32.5	7.8	0.8	3	6	0.6	20	23.4	27.2	11.5	11.2	3.14	5200			
18	NUCF18-AB	40	20	M18 × 1.5	19	21.5	58	36.5	8	0.8	3	6	1	22	25.2	30.9	21.2	14.4	3.72	4700			
20	NUCF20-AB	52	24	M20 × 1.5	21	25.5	66	40.5	9	0.8	4	8	1	31	43	58.1	27.1	23.2	8.23	3300			
20	NUCF20-1-AB	47	24	M20 × 1.5	21	25.5	66	40.5	9	0.8	4	8	1	27	38.9	48.9	24.8	21	7.15	3800			
24	NUCF24-AB	62	28	M24 × 1.5	25	30.5	80	49.5	11	1.3	4	8	1	38	57.6	74.3	34.3	32.9	10.5	2800			
24	NUCF24-1-AB	72	28	M24 × 1.5	25	30.5	80	49.5	11	1.3	4	8	1.1	44	63.3	87.5	49.5	38.2	12.9	2300			
30	NUCF30-AB	80	35	M30 × 1.5	32	37	100	63	15	1	4	8	1.1	47	94.8	135	73.7	52.6	14.9	2100			
30	NUCF30-2-AB	90	35	M30 × 1.5	32	37	100	63	15	1	4	8	1.1	47	94.8	135	73.7	59.3	17.3	2100			

Unit: mm

THK CO., LTD.

HEAD OFFICE 3-11-6, NISHI-GOTANDA, SHINAGAWA-KU, TOKYO 141-8503 JAPAN
INTERNATIONAL SALES DEPARTMENT PHONE:+81-3-5434-0351 FAX:+81-3-5434-0353

Global site : <http://www.thk.com/>

EUROPE

THK GmbH
●EUROPEAN HEADQUARTERS
Phone:+49-2102-7425-555 Fax:+49-2102-7425-556
●DÜSSELDORF OFFICE
Phone:+49-2102-7425-0 Fax:+49-2102-7425-299
●STUTTGART OFFICE
Phone:+49-7141-4988-500 Fax:+49-7141-4988-888
●U.K. OFFICE
Phone:+44-1384-47-1550 Fax:+44-1384-47-1551
●ITALY OFFICE
Phone:+39-02-9901-1801 Fax:+39-02-9901-1881
●SWEDEN OFFICE
Phone:+46-8-445-7630 Fax:+46-8-445-7639
●AUSTRIA OFFICE
Phone:+43-7229-51400 Fax:+43-7229-51400-79
●SPAIN OFFICE
Phone:+34-93-652-5740 Fax:+34-93-652-5746
●TURKEY OFFICE
Phone:+90-216-362-4050 Fax:+90-216-569-7150
●PRAGUE OFFICE
Phone:+420-2-41025-100 Fax:+420-2-41025-199
●MOSCOW OFFICE
Phone:+7-495-649-80-47 Fax:+7-495-649-80-44
THK Europe B.V.
●EINDHOVEN OFFICE
Phone:+31-040-290-9500 Fax:+31-040-290-9599
THK France S.A.S.
Phone:+33-4-3749-1400 Fax:+33-4-3749-1401

NORTH AMERICA

THK America, Inc.
●HEADQUARTERS
Phone:+1-847-310-1111 Fax:+1-847-310-1271
●CHICAGO OFFICE
Phone:+1-847-310-1111 Fax:+1-847-310-1182
●NORTH EAST OFFICE
Phone:+1-631-244-1565 Fax:+1-631-244-1565
●ATLANTA OFFICE
Phone:+1-770-840-7990 Fax:+1-770-840-7897
●LOS ANGELES OFFICE
Phone:+1-949-955-3145 Fax:+1-949-955-3149
●SAN FRANCISCO OFFICE
Phone:+1-925-455-8948 Fax:+1-925-455-8965
●DETROIT OFFICE
Phone:+1-248-858-9330 Fax:+1-248-858-9455
●TORONTO OFFICE
Phone:+1-905-820-7800 Fax:+1-905-820-7811
SOUTH AMERICA
THK BRAZIL INDUSTRIA E COMERCIO LTDA.
Phone:+55-11-3767-0100 Fax:+55-11-3767-0101
CHINA
THK (CHINA) CO., LTD.
●HEADQUARTERS
Phone:+86-411-8733-7111 Fax:+86-411-8733-7000
●SHANGHAI OFFICE
Phone:+86-21-6219-3000 Fax:+86-21-6219-9890
●BEIJING OFFICE
Phone:+86-10-8441-7277 Fax:+86-10-6590-3557

CHENGDU OFFICE

Phone:+86-28-8526-8025 Fax:+86-28-8525-6357
●GUANGZHOU OFFICE
Phone:+86-20-8523-8418 Fax:+86-20-3801-0456
●SHENZHEN OFFICE
Phone:+86-755-2642-9587 Fax:+86-755-2642-9604
●XIAN OFFICE
Phone:+86-29-8834-1712 Fax:+86-29-8834-1710
THK (SHANGHAI) CO., LTD.
Phone:+86-21-6275-5280 Fax:+86-21-6219-9890
TAIWAN
THK TAIWAN CO., LTD.
●TAIPEI HEAD OFFICE
Phone:+886-2-2888-3818 Fax:+886-2-2888-3819
●TAICHUNG OFFICE
Phone:+886-4-2359-1505 Fax:+886-4-2359-1506
●TAINAN OFFICE
Phone:+886-6-289-7668 Fax:+886-6-289-7669
KOREA
SEOUL REPRESENTATIVE OFFICE
Phone:+82-2-3468-4351 Fax:+82-2-3468-4353
SINGAPORE
THK LM SYSTEM Pte. Ltd.
Phone:+65-6884-5500 Fax:+65-6884-5550
THAILAND
THK LM System Pte. Ltd. Representative Office in Thailand
Phone:+660-2751-3001 Fax:+660-2751-3003
INDIA
THK India Pvt. Ltd.
Phone:+91-80-2340-9934 Fax:+91-80-2340-9937